



PART NUMBER: CS-3603


DESCRIPTION: solid state buzzer

SPECIFICATONS

operating voltage	2 ~ 4 V DC	
current consumption	50 mA max.	at 3 V DC
sound pressure level	75 db min.	at 30 cm/3 V DC
tone	continuous	
operating temperature	-20 ~ +60° C	
storage temperature	-30 ~ +70° C	
weight	9.7 g max.	
RoHS	yes	

APPEARANCE DRAWING

tolerance: ± 0.5
units: mm

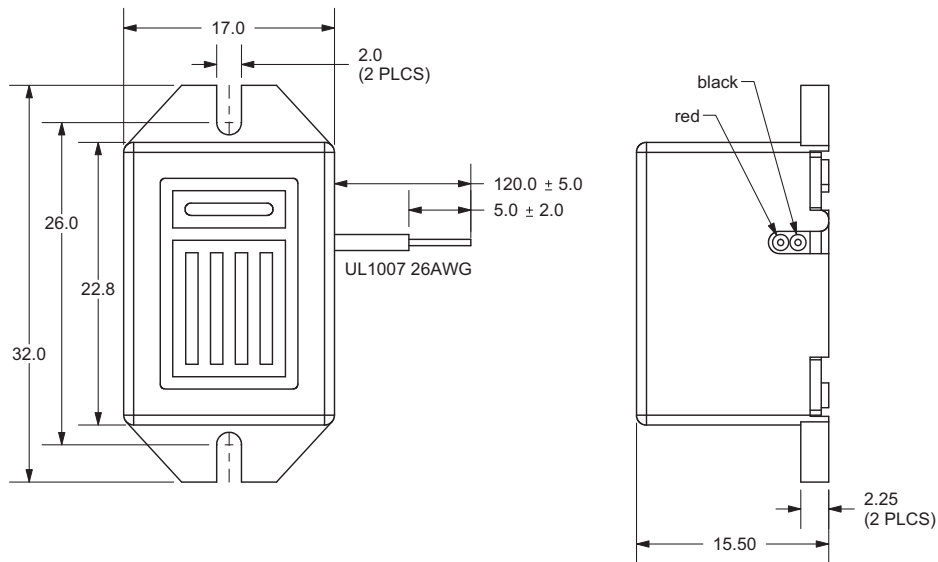

CURRENT CONSUMPTION/SOUND PRESSURE LEVEL

