

PART NUMBER: CS-8406


DESCRIPTION: SOLID STATE BUZZER

SPECIFICATIONS

parameter	conditions/description	min	nom	max	units
operating voltage		4		8	Vdc
current consumption	at 6 Vdc			25	mA
sound pressure level	at 30 cm / 6 Vdc	75			dB
tone	continuous				
operating temperature		-20		60	°C
storage temperature		-30		70	°C
weight				8.5	g
RoHS	yes				

APPEARANCE DRAWING

tolerance: ±0.5
 units: mm

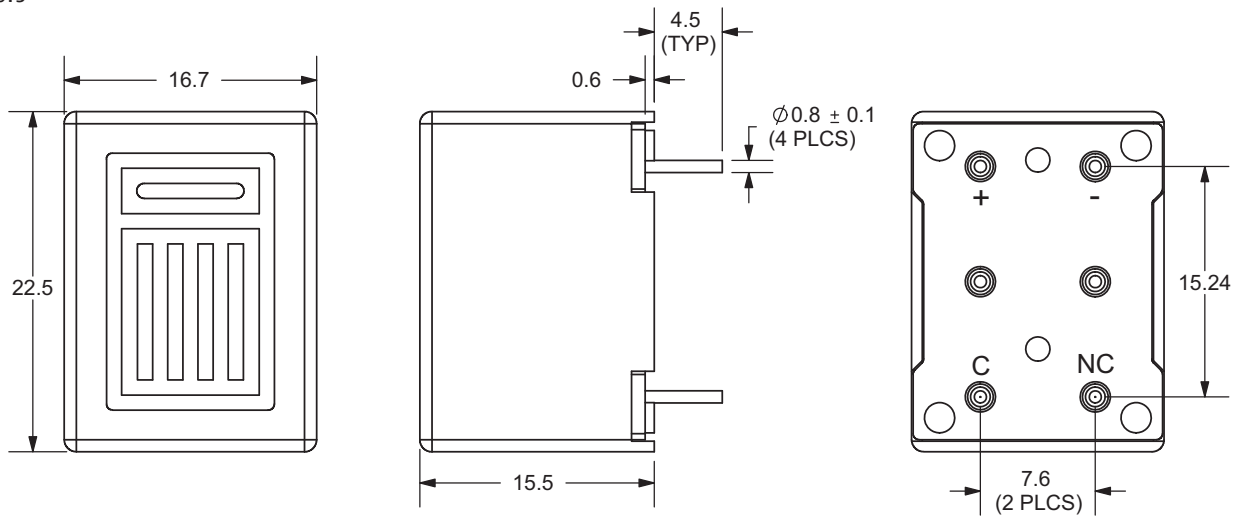

CURRENT CONSUMPTION / SOUND PRESSURE LEVEL

Tolerance: ±0.5mm

