

**PART NUMBER: CS-8406**


**DESCRIPTION: SOLID STATE BUZZER**

## SPECIFICATIONS

parameter	conditions/description	min	nom	max	units
operating voltage		4		8	Vdc
current consumption	at 6 Vdc			25	mA
sound pressure level	at 30 cm / 6 Vdc	75			dB
tone	continuous				
operating temperature		-20		60	°C
storage temperature		-30		70	°C
weight				8.5	g
RoHS	yes				

## APPEARANCE DRAWING

tolerance: ±0.5  
 units: mm

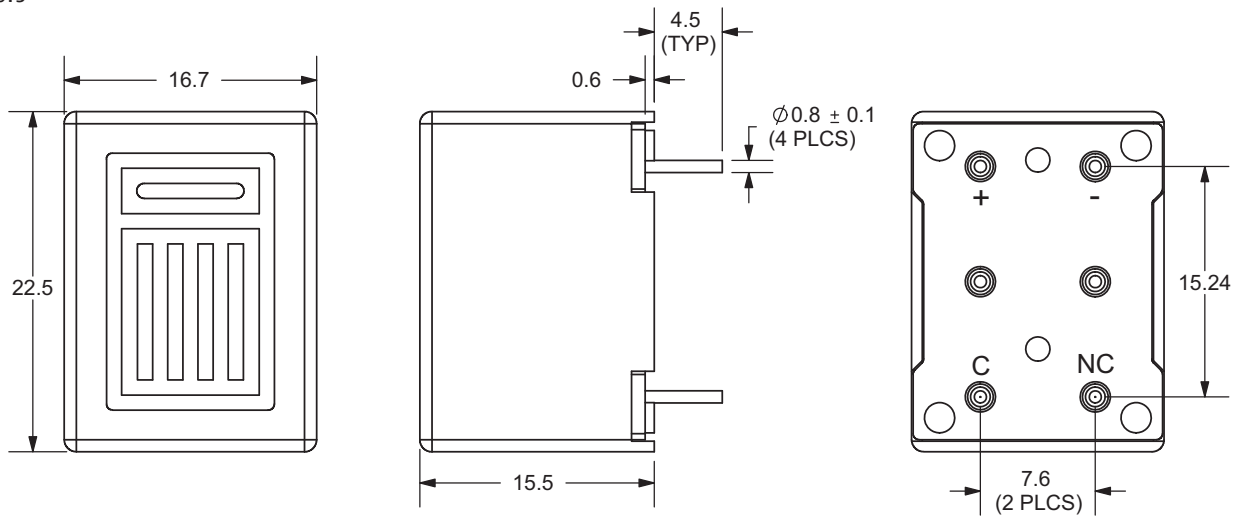

## CURRENT CONSUMPTION / SOUND PRESSURE LEVEL

Tolerance: ±0.5mm

