


REV.	DESCRIPTION	DATE
A	NEW DRAWING	05/14/2010

● Specifications

Supply Voltage	DC5V ± 5%	Resolution	100P/R
Supply Current	30mA Max.	Frequency Response	500Hz
Output	Incremental	Rotational Life	2,500,000
Phase Difference	90 ± 45°	Operational Torque	50gfcMMax.
Output Wave	Rectangle Wave	Click	Without Click
Operating Temperature Range	0 ~ +60°C	Weight (Approx.)	28g
Storage Temperature Range	-20 ~ +80°C		

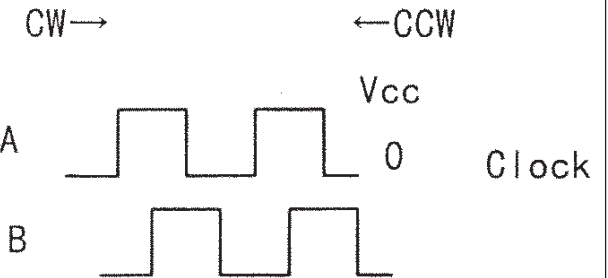

Output wave



20050 SW 112th Ave.  
 Tualatin, OR 97062  
 Phone: 503-612-2300  
 800-275-4899  
 Fax: 503-612-2383  
 Website: www.cui.com



TITLE: optical encoder		REV: A
PART NO. EC202V100A	UNITS: MM	
DRAWN BY: JRH	APPROVED BY:	SCALE: